


Meter housing

GTZ 22-t-eHZ

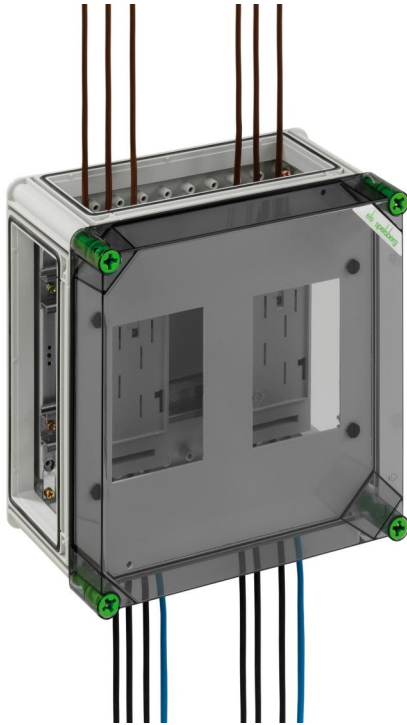

GTZ 22-t-eHZ

Meter housing

CUSTOMIZABLE

Productnumber: 02020201

Dimensions: 320 x 320 x 179 mm

Meter housing - Industrial Quality -, with two assembled BKE-I for electronic domestic supply meters, incl. connecting pipes 1000 mm, for input/output, with sealing kit, with fixing screws, 3 x enclosure connectors (GGV)

with transparent cover



Technical Data

electrical characteristics

Rated operating voltage AC:	400 V
Protection class:	II
Type of protection:	IP65
UL Type Rating:	3R
Meter type:	eHZ

Colours

Base unit colour:	grey
-------------------	------

Dimensions

Width:	320 mm
Length:	320 mm
Height:	179 mm

Material characteristics

UV-resistant:	yes
Halogen free:	yes
Flammability class according with UL94:	V2
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	yes

mechanical properties

Type of fastening:	Surface mounting
Impact strength:	IK08
Cover screw torque:	2.5 Nm
Stackable:	yes

Ambient conditions

max. relative humidity 25°C:	95 %
------------------------------	------

Ambient conditions

max. relative humidity 40°C:	50 %
Min. ambient temperature:	-25 °C
Max. ambient temperature:	40 °C
24h ambient temperature:	35 °C
Installation location:	protected outdoor areas

Material

Base unit material:	Polycarbonate
Cover material:	Polycarbonate
Sealing material:	Polyurethane
Cover screw material:	Polyamide, glass-fibre reinforced
Hinged window material:	Polycarbonate

Accessories

[07251201 - GFS 12-m - Flange set](#)