


Busbar enclosures

GSI 123-NPE

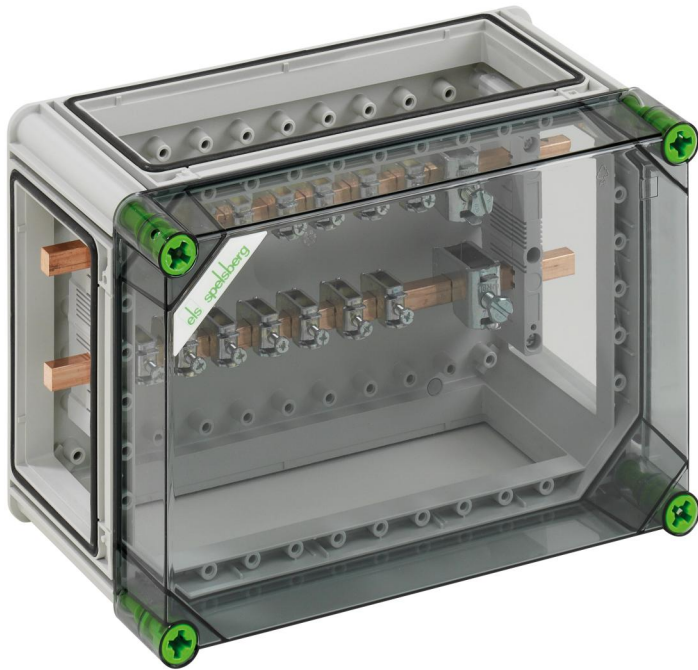

GSI 123-NPE

Busbar enclosures

Productnumber: 04012301

Dimensions: 220 x 320 x 179 mm

Busbar housing - Industrial Quality -, 2 poles, 250 A, N: 12 x 10 mm, with copper rails, PE: 12 x 10 mm, with 14 busbar terminals 1.5 - 16 mm², with 2 busbar terminals 16 - 70 mm², 3 x enclosure connectors (GGV)

with transparent cover



Technical Data

electrical characteristics

Rated operating voltage AC:	690 V
Protection class:	II
Type of protection:	IP65
with rail system:	yes
UL Type Rating:	3R

Dimensions

Width:	220 mm
Length:	320 mm
Height:	179 mm

Material characteristics

UV-resistant:	yes
Halogen free:	yes
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	yes

mechanical properties

Type of fastening:	Surface mounted
Impact strength:	IK08
Cover screw torque:	2.5 Nm
Stackable:	yes

Ambient conditions

Min. ambient temperature:	-35 °C
Max. ambient temperature:	80 °C
24h ambient temperature:	60 °C
Installation location:	protected outdoor areas

Material

Base unit material:	Plastic
---------------------	---------

Accessories

[07251101 - GFS 11-m - Flange set](#)