


Flange

GFL 411-m

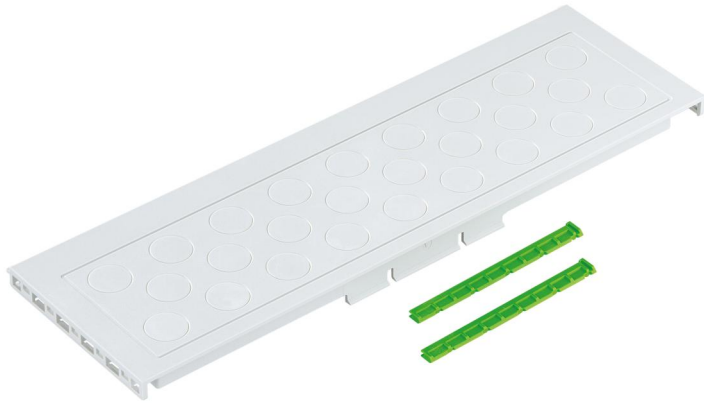

GFL 411-m

Flange

Productnumber: 07241101

Dimensions: 395 x 119 x 15 mm

Flange with metric knockouts, 2 x flange connectors (GFV)

**Pre-stamped for cable insertion: 1x M40/M32,
16x M25/M20**

IP65

Technical Data

electrical characteristics

Type of protection:	IP65
UL Type Rating:	3R

Colours

Accessory colour:	light grey
-------------------	------------

Dimensions

Width:	395 mm
Length:	119 mm
Height:	15 mm

Material characteristics

UV-resistant:	yes
Industry quality:	yes

Ambient conditions

Installation location:	protected outdoor areas
------------------------	-------------------------

Material

Accessory material:	Polycarbonate, glass-fibre reinforced
---------------------	---------------------------------------

Accessories

[26344001 - BEL Air M40 - Ventilation element set](#)