


Busbar terminal

SKL 015

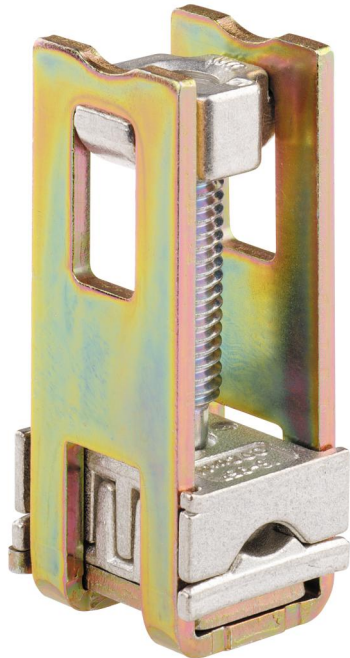

SKL 015

Busbar terminal

Productnumber: 07501501

Dimensions: 25 x 30 x 83 mm

Busbar terminal, for rails 12 x 5 mm / 12 x 10 mm,
for aluminium and copper conductors

**for AL/CU conductors 1x (16-50)re, 1x
(16-150)rm, 1x (50-150)se, 1x (35-150)sm**

150²

Technical Data

electrical characteristics

Max. conductor cross section:	150 mm ²
Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	1
Connection 1: Connectable conductor cross-section, single-wire (min):	16 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	50 mm ²
Connection 1: Connectable conductor cross-section, stranded (min):	16 mm ²
Connection 1: Connectable conductor cross-section, stranded (max):	150 mm ²

Dimensions

Width:	25 mm
Length:	30 mm
Height:	83 mm

Material characteristics

Industry quality:	no
-------------------	----

mechanical properties

Connection 1: Tightening moment:	20 Nm
----------------------------------	-------