


Busbar terminal

## SKL 535

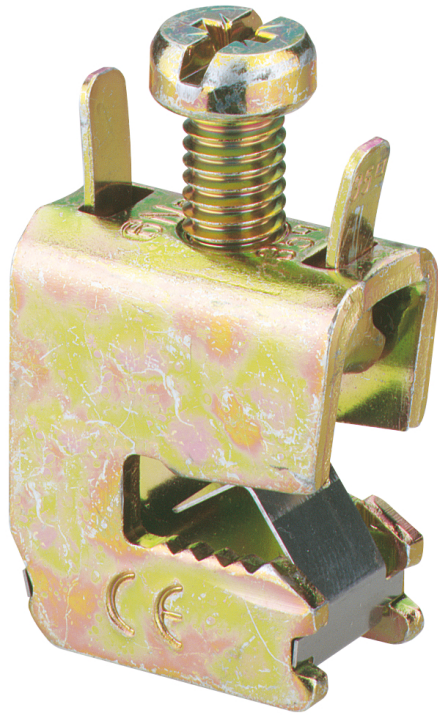

### SKL 535

**Busbar terminal**

Productnumber: 07553501

Dimensions: 16 x 26,5 x 31,5 mm

Bus bar terminals for copper rails 12/20/25/30 x 5 mm

**Connection for Cu 1.5-35 mm<sup>2</sup>, Flat copper 160 A**

35<sup>2</sup>

## Technical Data

### electrical characteristics

Max. conductor cross section:	35 mm <sup>2</sup>
Rated current:	270 A
Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	0
Connection 1: Connectable conductor cross-section, single-wire (min):	4 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, single-wire (max):	35 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (min):	4 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (max):	35 mm <sup>2</sup>

### Dimensions

Width:	16 mm
Length:	26.5 mm
Height:	31.5 mm

### Material characteristics

Industry quality:	no
-------------------	----

### mechanical properties

Connection 1: Tightening moment:	6 Nm
----------------------------------	------