


PEN terminal

## GN 3

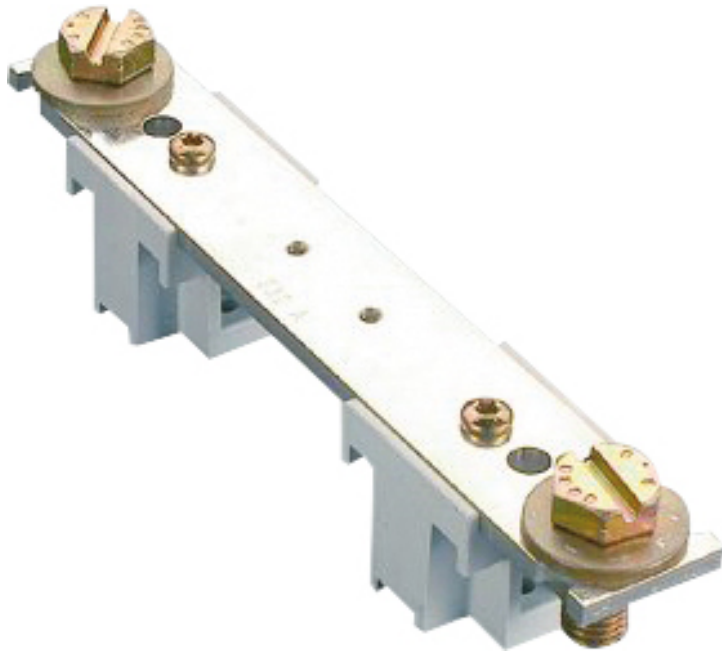

### GN 3

**PEN terminal**

Productnumber: 07603201

Dimensions: 37 x 198 x 46 mm

for mounting plate

**N terminal NH 3 for mounting plate, Connection screw M12**

---

## Technical Data

### electrical characteristics

Rated operating voltage AC:	690 V
Rated operating voltage DC:	440 V
Rated current:	630 A
Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	2
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	0

### Dimensions

Width:	37 mm
Length:	198 mm
Height:	46 mm

### Material characteristics

Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	no

### Material

Insulating body material:	Thermoplastic
---------------------------	---------------