


Busbar terminal

## SKLAL 118

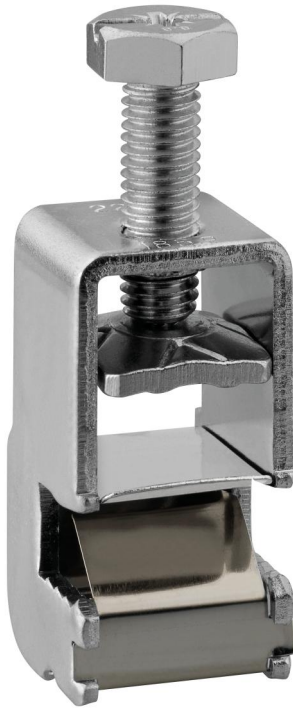

### SKLAL 118

**Busbar terminal**

Productnumber: 07611801

Dimensions: 28,5 x 29 x 53 mm

Busbar terminal, for copper rails 12/20/25/30 x 10 mm

**for AL/CU-Conductors 1x (50-185mm<sup>2</sup>)  
re/rm/rf+AE, 1x (50-185mm<sup>2</sup>) SM**

## Technical Data

### electrical characteristics

|   |                     |
|---|---------------------|
| Max. conductor cross section:   | 185 mm <sup>2</sup> |
| Number of poles:  | 1                   |
| shockproof:   | No                  |
| Connection 1: Connection type:  | Screws              |
| Connection 1: Clamping points per pole:                               | 1                   |
| Connection 1: Suitable for Cu conductors:                             | 1                   |
| Connection 1: Suitable for Al conductors:                             | 1                   |
| Connection 1: Connectable conductor cross-section, single-wire (min): | 50 mm <sup>2</sup>  |
| Connection 1: Connectable conductor cross-section, single-wire (max): | 185 mm <sup>2</sup> |
| Connection 1: Connectable conductor cross-section, stranded (min):    | 50 mm <sup>2</sup>  |
| Connection 1: Connectable conductor cross-section, stranded (max):    | 185 mm <sup>2</sup> |

### Dimensions

|         |         |
|---------|---------|
| Width:  | 28.5 mm |
| Length: | 29 mm   |
| Height: | 53 mm   |

### Material characteristics

|                   |    |
|-------------------|----|
| Industry quality: | no |
|-------------------|----|

### mechanical properties

|                                  |       |
|----------------------------------|-------|
| Connection 1: Tightening moment: | 22 Nm |
|----------------------------------|-------|