


Prism terminal

## KP NH 00

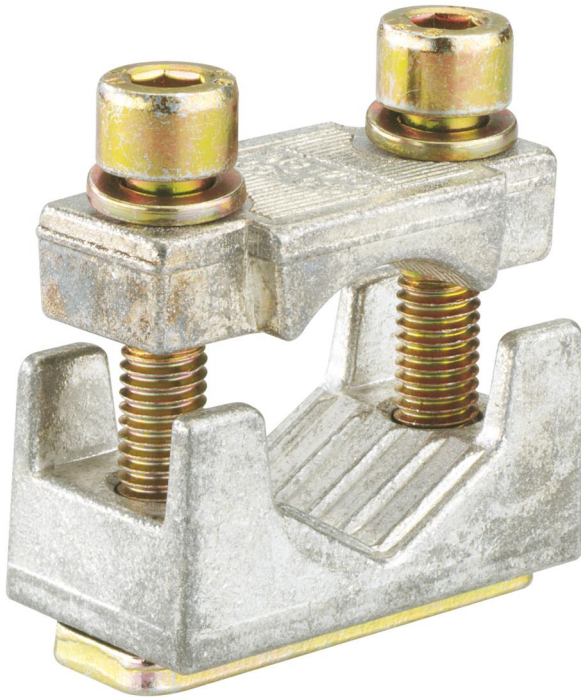

### KP NH 00

#### Prism terminal

Productnumber: 07670001

Dimensions: 27 x 20,2 x 21 mm

Prism terminal for connecting aluminium and copper conductors to PE and N terminals (GPE, GN) and to NH switchgear in AKi fuse and switch housings (AKi-SS, AKi-ST)

**for AL/CU conductors 1x (16-70)rm/rf/sm, aluminium conductor see technical appendix, Set = 3 pcs.**

## Technical Data

### electrical characteristics

Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	1
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (min):	16 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (max):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	16 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, single-wire (min):	16 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, single-wire (max):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (min):	16 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (max):	70 mm <sup>2</sup>

### Dimensions

Width:	27 mm
Length:	20.2 mm
Height:	21 mm

### Material characteristics

Industry quality:	no
-------------------	----

### mechanical properties

Connection 1: Tightening moment:	3.6 Nm
----------------------------------	--------