

Prism terminal

KP NH 2

KP NH 2


Prism terminal

Productnumber: 07670201

Dimensions: 27 x 20,2 x 21 mm

Prism terminal for connecting aluminium and copper conductors to PE and N terminals (GPE, GN) and to NH switchgear in AKi fuse and switch housings (AKi-SS, AKi-ST)

for AL/CU conductors 1x (50-240)rm/rf/sm, aluminium conductor see technical appendix, Set = 1 pcs.

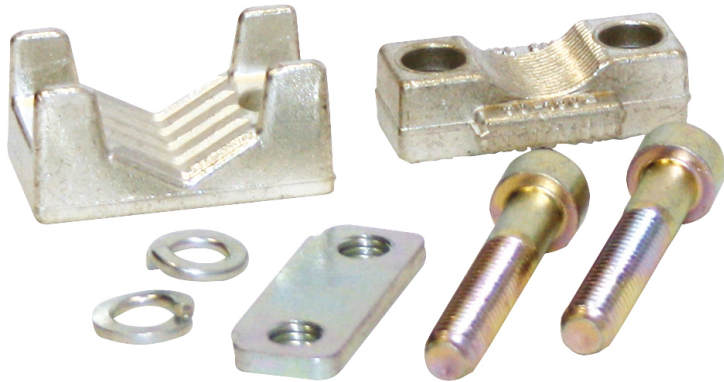

Technical Data

electrical characteristics

Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	1
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (min):	50 mm ²
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (max):	240 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	50 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	240 mm ²
Connection 1: Connectable conductor cross-section, single-wire (min):	50 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	240 mm ²
Connection 1: Connectable conductor cross-section, stranded (min):	50 mm ²
Connection 1: Connectable conductor cross-section, stranded (max):	240 mm ²

Dimensions

Width:	27 mm
Length:	20.2 mm
Height:	21 mm

Material characteristics

Industry quality:	no
-------------------	----