


Flat terminal clamp

## **KF NH 1**

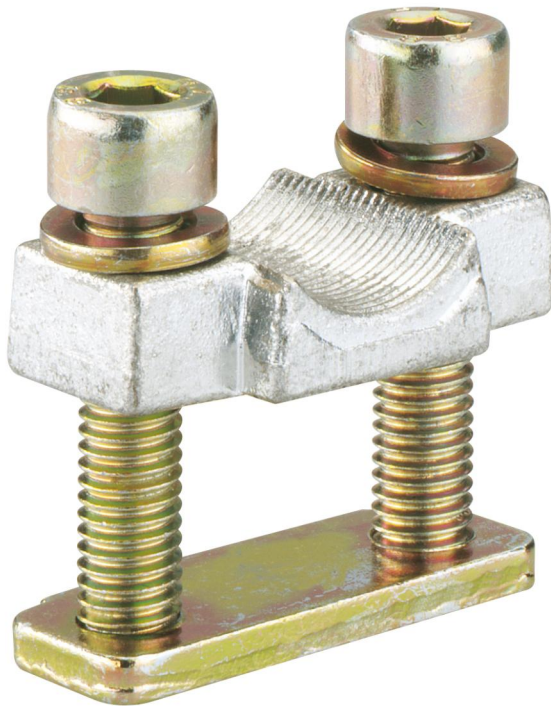

### **KF NH 1**

#### **Flat terminal clamp**

Productnumber: 07671101

Dimensions: 120 x 80 x 10 mm

for NH fuse base, for NH fuse switch disconnecter,  
for PE/N terminals, for copper conductors, for  
laminated flat copper

**Clamp connection, for CU conductors 1x  
(70-150)mm<sup>2</sup>, laminated flat copper 18 x 2-14  
mm**

## Technical Data

### electrical characteristics

shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	0
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (min):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (max):	150 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	150 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, single-wire (min):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, single-wire (max):	150 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (min):	70 mm <sup>2</sup>
Connection 1: Connectable conductor cross-section, stranded (max):	150 mm <sup>2</sup>

### Dimensions

Width:	120 mm
Length:	80 mm
Height:	10 mm

### Material characteristics

Industry quality:	no
-------------------	----