


Flat terminal clamp

KF NH 3

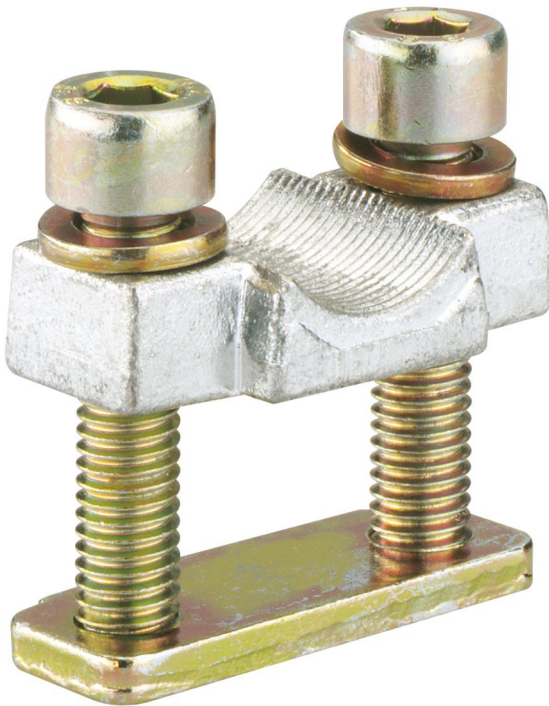

KF NH 3

Flat terminal clamp

Productnumber: 07671301

Dimensions: 17 x 58,5 x 30 mm

for NH fuse base, for NH fuse switch disconnecter,
for PE/N terminals, for copper conductors, for
laminated flat copper

**Clamp connection, for CU conductors 1x
(150-300)mm²/mm², Laminated flat copper 25 x 1-13
mm**

Technical Data

electrical characteristics

shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	0
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (min):	150 mm ²
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (max):	300 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	150 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	300 mm ²
Connection 1: Connectable conductor cross-section, single-wire (min):	150 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	300 mm ²
Connection 1: Connectable conductor cross-section, stranded (min):	150 mm ²
Connection 1: Connectable conductor cross-section, stranded (max):	300 mm ²

Dimensions

Width:	17 mm
Length:	58.5 mm
Height:	30 mm

Material characteristics

Industry quality:	no
-------------------	----