


Tunnel terminal

KB NH 00

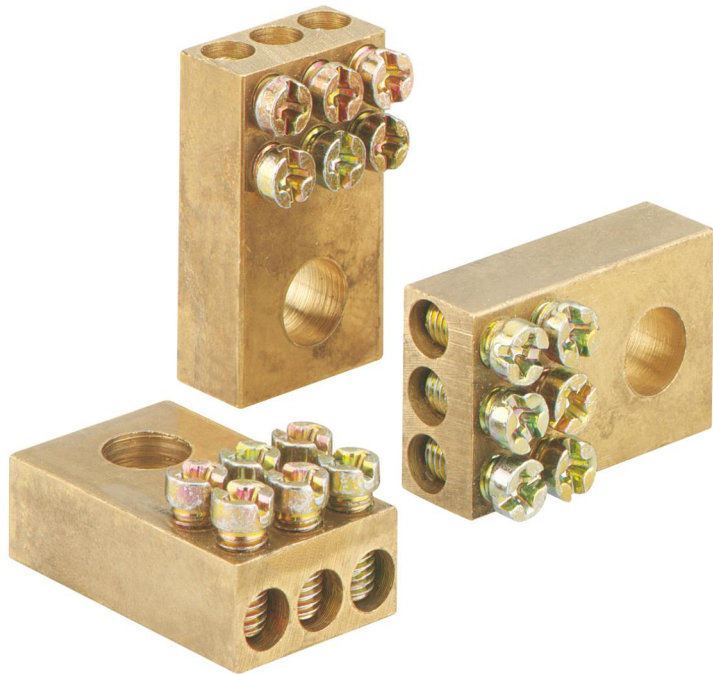

KB NH 00

Tunnel terminal

Productnumber: 07672001

Dimensions: 22 x 40 x 18 mm

Tunnel terminal for NH 00 fuse switch disconnecter
for connecting 3 x 1.5-16 mm²

Set = 3 pcs.

Technical Data

electrical characteristics

shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	0
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	2.5 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	16 mm ²
Connection 1: Connectable conductor cross-section, single-wire (min):	2.5 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	25 mm ²
Connection 1: Connectable conductor cross-section, stranded (min):	2.5 mm ²
Connection 1: Connectable conductor cross-section, stranded (max):	25 mm ²
Connection 2: Connection type:	Screws
Connection 2: Suitable for Cu conductors:	1
Connection 2: Suitable for Al conductors:	0
Connection 2: Connectable conductor cross-section, fine-wire with ferrule (min):	2.5 mm ²
Connection 2: Connectable conductor cross-section, fine-wire with ferrule (max):	10 mm ²
Connection 2: Connectable conductor cross-section, single-wire (min):	2.5 mm ²
Connection 2: Connectable conductor cross-section, single-wire (max):	16 mm ²
Connection 2: Connectable conductor cross-section, stranded (min):	2.5 mm ²
Connection 2: Connectable conductor cross-section, stranded (max):	16 mm ²

Dimensions

Width:	22 mm
Length:	40 mm

Dimensions

Height:	18 mm
---------	-------

Material characteristics

Industry quality:	no
-------------------	----

mechanical properties

Connection 1: Tightening moment:	2 Nm
----------------------------------	------