


Terminal block enclosure

ALR 1808-4²

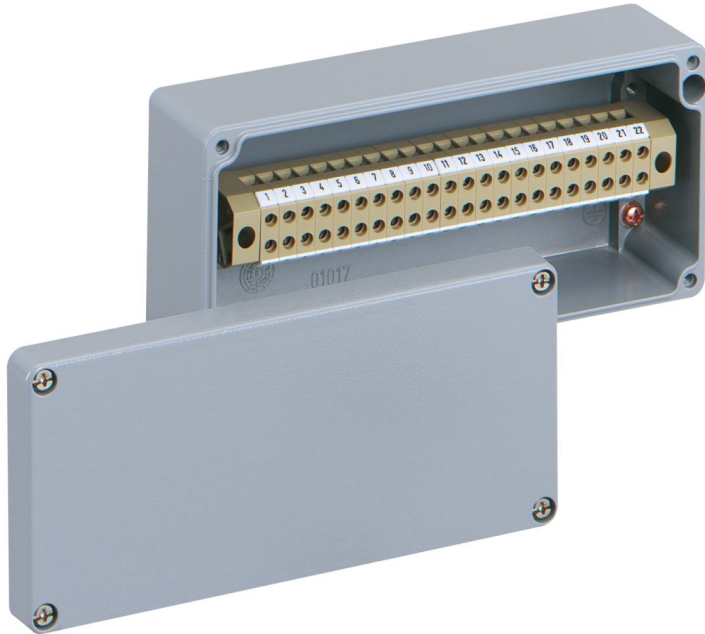

ALR 1808-4²

Terminal block enclosure

CUSTOMIZABLE

Productnumber: 16040701

Dimensions: 175 x 80 x 57 mm

Terminal block enclosure, protection class IP66, nominal cross-section 4 mm², Ui=400V AC, Aluminium, powder-coated painting, internal fixing points, for installations in industrial environments and protected outdoor areas

**equipped with 22-pole terminal block 4mm²
(Contaclip BKA 4 type)**



Technical Data

electrical characteristics

Rated insulation voltage AC:	400 V
Max. conductor cross section:	4 mm ²
Type of protection:	IP66
UL Type Rating:	not specified

Dimensions

Width:	175 mm
Length:	80 mm
Height:	57 mm

Material characteristics

UV-resistant:	yes
Halogen free:	yes
Industry quality:	yes

mechanical properties

Type of fastening:	Wall/ceiling mounting
Impact strength:	IK09
Sealable:	yes
Fastening:	internal fixing points

Ambient conditions

max. relative humidity 25°C:	95 %
max. relative humidity 40°C:	50 %
Min. ambient temperature:	-35 °C
Max. ambient temperature:	75 °C
24h ambient temperature:	60 °C
Installation location:	protected outdoor areas

Material

Base unit material:	Aluminium, powder-coated painting
Cover material:	Aluminium, powder-coated painting
Sealing material:	Polyurethane

Accessories

[15400401 - AL ALS-kl - External attachment set](#)