


Terminal block

WK 100 KLS-10²

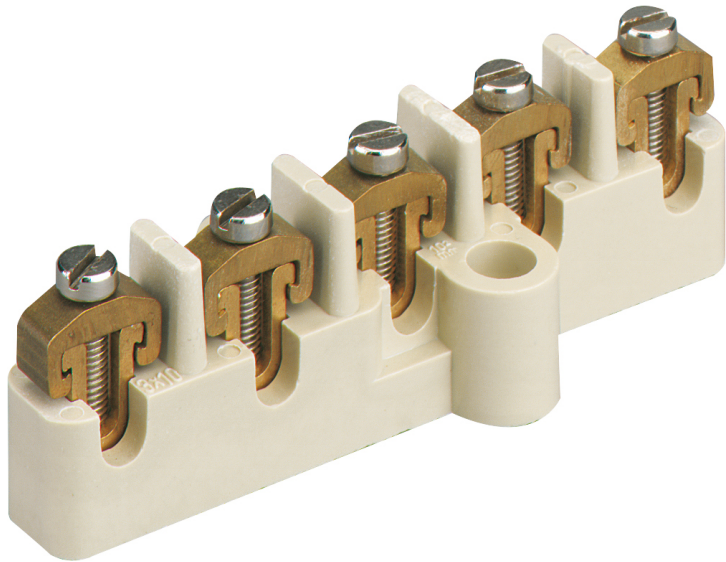

WK 100 KLS-10²

Terminal block

Productnumber: 46051001

Dimensions: 33 x 96 x 26,5 mm

Connecting terminal, $U_i=400V / 690V$

5x10 mm², for K15, K3-, K4-EK boxes

Technical Data

electrical characteristics

Rated operating voltage AC:	690 V
Number of poles:	5
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Connectable conductor cross-section, single-wire (min):	4 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	10 mm ²

Dimensions

Width:	33 mm
Length:	96 mm
Height:	26.5 mm

Material characteristics

Flammability class according with UL94:	V0
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	no

mechanical properties

Connection 1: Tightening moment:	2 Nm
----------------------------------	------

Material

Insulating body material:	Duroplast
---------------------------	-----------