

Terminal block

WK 160 KLS-16²

WK 160 KLS-16²


Terminal block

Productnumber: 46051601

Dimensions: 38 x 120 x 32 mm

Connecting terminal, $U_i=400V / 690V$

5x16 mm², for K3-, K4-EK boxes

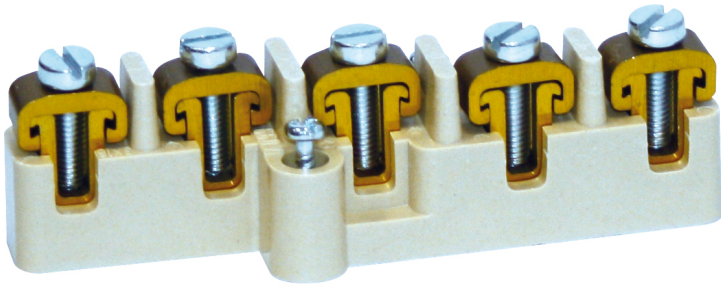

Technical Data

electrical characteristics

Rated operating voltage AC:	690 V
Number of poles:	5
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	1
Connection 1: Suitable for Cu conductors:	1
Connection 1: Connectable conductor cross-section, single-wire (min):	6 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	16 mm ²

Dimensions

Width:	38 mm
Length:	120 mm
Height:	32 mm

Material characteristics

Flammability class according with UL94:	V0
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	no

Material

Insulating body material:	Duroplast
---------------------------	-----------