

Terminal

URS RK1-240mm²

URS RK1-240mm²


Terminal

Productnumber: 67074001

Dimensions: 36 x 109 x 112,8 mm

Connecting terminal, 1-pole, stackable, for one or more-wired leads and for laminated flat copper

Upgrade kit for 5-pole 1-pole

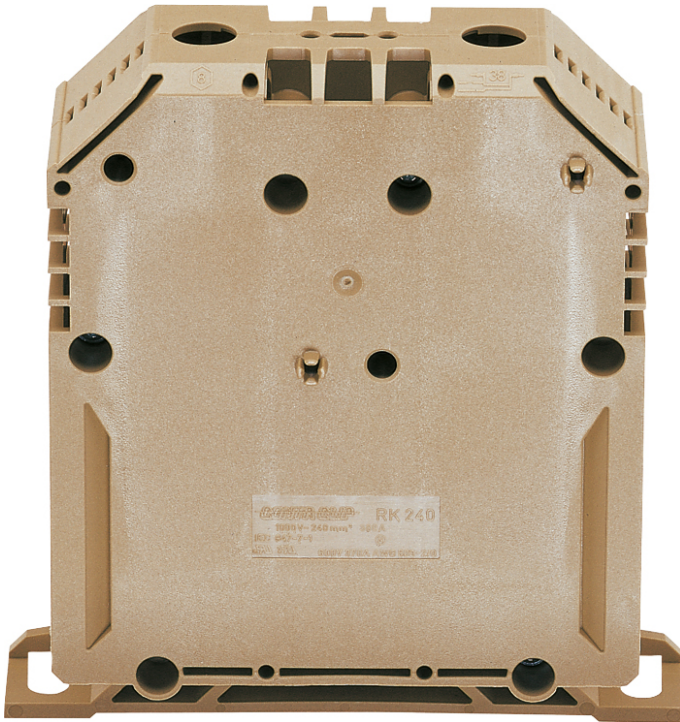

Technical Data

electrical characteristics

Rated operating voltage AC:	690 V
Rated operating voltage DC:	750 V
Rated insulation voltage AC:	1000 V
Rated connecting capacity:	240 mm ²
Rated current:	380 A
Number of poles:	1
shockproof:	No
Connection 1: Connection type:	Screws
Connection 1: Strip length:	37 mm
Connection 1: Clamping points per pole:	2
Connection 1: Suitable for Cu conductors:	1
Connection 1: Suitable for Al conductors:	1
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (min):	70 mm ²
Connection 1: Connectable conductor cross-section, fine-wire without ferrule (max):	240 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (min):	70 mm ²
Connection 1: Connectable conductor cross-section, fine-wire with ferrule (max):	185 mm ²
Connection 1: Connectable conductor cross-section, single-wire (min):	70 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	240 mm ²
Connection 1: Connectable conductor cross-section, stranded (min):	70 mm ²
Connection 1: Connectable conductor cross-section, stranded (max):	240 mm ²

Dimensions

Width:	36 mm
Length:	109 mm
Height:	112.8 mm

Material characteristics

Flammability class according with UL94:	V2
Industry quality:	no

mechanical properties

Connection 1: Tightening moment:	20 Nm
----------------------------------	-------

Material

Insulating body material:	Thermoplastic
---------------------------	---------------