

Terminal block

Abox 100 KLS-10²

Abox 100 KLS-10²


Terminal block

Productnumber: 84001001

Dimensions: 35,7 x 241,4 x 13 mm

Connecting terminal acc. to DIN EN 60998 (VDE 0613), $U_i=690V$

5-pole - 10 mm²

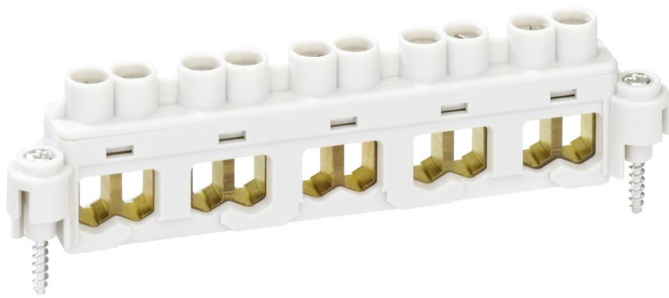

Technical Data

electrical characteristics

Rated operating voltage AC:	690 V
Rated current:	76 A
Number of poles:	5
shockproof:	Yes
Connection 1: Connection type:	Screws
Connection 1: Clamping points per pole:	2
Connection 1: Suitable for Cu conductors:	1
Connection 1: Connectable conductor cross-section, single-wire (min):	2.5 mm ²
Connection 1: Connectable conductor cross-section, single-wire (max):	16 mm ²

Dimensions

Width:	35.7 mm
Length:	241.4 mm
Height:	13 mm

Material characteristics

Flammability class according with UL94:	V2
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	no

Material

Insulating body material:	Thermoplastic
---------------------------	---------------

Certificates

Test mark:	VDE (DIN 60998-1/-2-1 (VDE 0613-1/-2-1))
------------	--