

Junction box

## WKE 5 - 15 x 6<sup>2</sup>

This product is outdated. To the successor product: <https://www.spelsberg.com/p/86851601>

### WKE 5 - 15 x 6<sup>2</sup>

Junction box

CUSTOMIZABLE

Productnumber: 86050501

Dimensions: 171 x 256 x 106 mm


Junction box, protection class IP54/IP65, nominal cross-section 6 mm<sup>2</sup>, U<sub>i</sub>=450 V AC, certified by VDE (DIN EN 60670-1/-22 (VDE 0606-1/-22)), knockouts, M20/M40, (16 side), external fixing lugs, with E30 - E 90 electrical functional integrity according to DIN 4102 Part 12. Halogen-free enclosure made of special thermosetting plastic, terminals made of special high-temperature-resistant ceramic.

**orange, Connection box 15-pole 0.5 - 6 mm<sup>2</sup>, number of clampable wires per**

**pole: 8 x 0.5<sup>2</sup> / 4 x 0.75<sup>2</sup> / 6 x 1<sup>2</sup> / 6 x 1.5<sup>2</sup> / 2 x 2.5<sup>2</sup> / 2 x 4<sup>2</sup> / 2 x 6<sup>2</sup>**

**Accessories supplied:**

**6 off IP54 attachment bushes M20, sealing range 8 - 13 mm, 2 off IP54 attachment busches M40, sealing range 17 - 30 mm, 2 off IP54 double end connectors M40, sealing range 17 - 30 mm, 1 off IP54 sealing plug M20, sealing range 8 - 13.5 mm, 1 off IP54 sealing plug M40, sealing range 17 - 30 mm, Drilling template, D6 wall + ceiling attachment set, Sealing set**

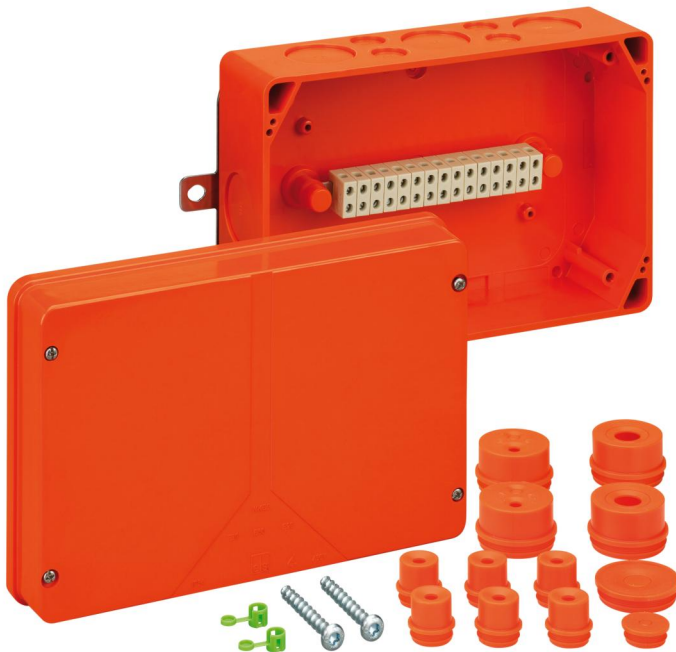

## Technical Data

### electrical characteristics

Rated insulation voltage AC:	450 V
Rated insulation voltage DC:	450 V
Max. conductor cross section:	6 mm <sup>2</sup>
Protection class:	II
Type of protection:	IP54/IP65
Circuit integrity class:	E30/E60/E90
UL Type Rating:	not specified

### Colours

Base unit colour:	orange
Cover colour:	orange

### Dimensions

Width:	171 mm
Length:	256 mm
Height:	106 mm

### Material characteristics

UV-resistant:	yes
Halogen free:	yes
Flammability class according with UL94:	V0
Glow-wire flammability according to EN 60695-2-11:	960 °C
Industry quality:	no

### mechanical properties

Type of fastening:	Wall/ceiling mounting
Sealable:	no
Cover screw torque:	1.8 Nm
Fastening:	external fixing lugs

### Ambient conditions

max. relative humidity 25°C:	95 %
max. relative humidity 40°C:	50 %
Min. ambient temperature:	-25 °C
Max. ambient temperature:	40 °C
24h ambient temperature:	35 °C
Installation location:	Indoors

### Material

Base unit material:	Duroplast
Cover material:	Duroplast
Sealing material:	Polyurethane
Cover screw material:	Stainless steel V2A

### Certificates

Test mark:	VDE (DIN EN 60670-1/-22 (VDE 0606-1/-22))
------------	---

## Accessories

[22762001 - KVR M20-MGM/or - Cable gland](#)

[22762501 - KVR M25-MGM/or - Cable gland](#)

[22763201 - KVR M32-MGM/or - Cable gland](#)

[22764001 - KVR M40-MGM/or - Cable gland](#)

[23062001 - AST M20/or - Attachment bushes](#)

[23062501 - AST M25/or - Attachment bushes](#)

[23063201 - AST M32/or - Attachment bushes](#)

[23064001 - AST M40/or - Attachment bushes](#)

[23162001 - VST M20/or - Sealing plugs](#)

[23162501 - VST M25/or - Sealing plugs](#)

[23163201 - VST M32/or - Sealing plugs](#)

[23164001 - VST M40/or - Sealing plugs](#)