


Junction box

HWK 2

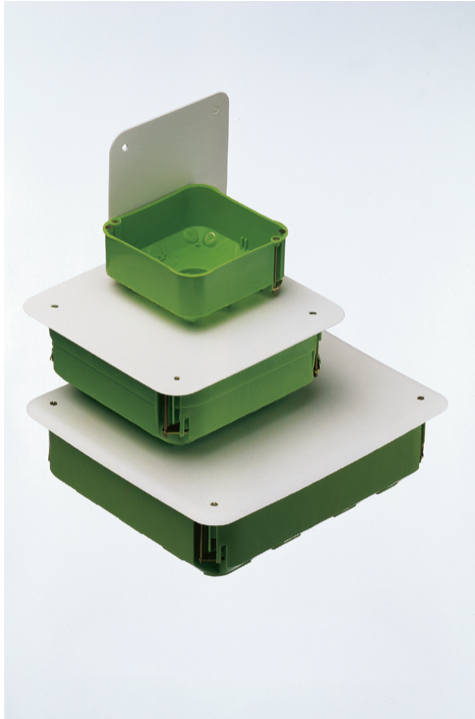

HWK 2

Junction box

Productnumber: 92800201

Dimensions: 165 x 165 x 72 mm

Cavity wall terminal boxes, flame resistant, for plate thicknesses from 7 to 35 mm, including white sealing cap

165 x 165 x 72 mm, with drilling template for 68 mm drilled holes

IP30 400V
AC

Technical Data

electrical characteristics

| | |
|------------------------------|---------------|
| Rated insulation voltage AC: | 400 V |
| Type of protection: | IP30 |
| UL Type Rating: | not specified |

Dimensions

| | |
|---------|--------|
| Width: | 165 mm |
| Length: | 165 mm |
| Height: | 72 mm |

Material characteristics

| | |
|--|--------|
| Halogen free: | no |
| Flammability class according with UL94: | HB |
| Glow-wire flammability according to EN 60695-2-11: | 850 °C |
| Industry quality: | no |

Ambient conditions

| | |
|------------------------------|---------|
| max. relative humidity 25°C: | - % |
| max. relative humidity 40°C: | 50 % |
| Min. ambient temperature: | -25 °C |
| Max. ambient temperature: | 40 °C |
| 24h ambient temperature: | 35 °C |
| Installation location: | Indoors |

Material

| | |
|---------------------|---------------|
| Base unit material: | Polypropylene |
| Cover material: | Polypropylene |