


Receptacle

U 71 GRD-D

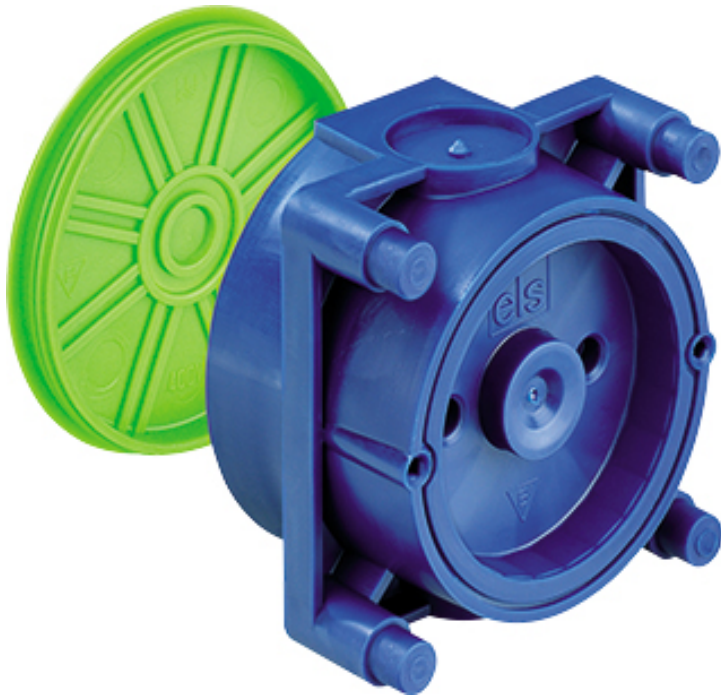

U 71 GRD-D

Receptacle

Productnumber: 97104502

Dimensions: 71 x 71 x 50 mm

Receptacle, for extremely thin walls, only 45 mm deep, combinable with corresponding binocular-like connectors, protection class IP30, rated insulation voltage: 400V AC, certified by VDE (DIN EN 60670-1/-22 (VDE 0606-1/-22)), Halogen free

magnet and nail installation, membrane for perforation, sealing range M16 - M20, support spar compatible



Technical Data

electrical characteristics

Rated insulation voltage AC:	400 V
Type of protection:	IP30
UL Type Rating:	not specified

Colours

Cover colour:	other
---------------	-------

Dimensions

Width:	71 mm
Length:	71 mm
Height:	50 mm

Material characteristics

Halogen free:	yes
Industry quality:	no

mechanical properties

Type of fastening:	magnet and nail installation
--------------------	------------------------------

Ambient conditions

max. relative humidity 25°C:	- %
max. relative humidity 40°C:	50 %
Min. ambient temperature:	-25 °C
Max. ambient temperature:	40 °C
24h ambient temperature:	35 °C

Material

Base unit material:	Polypropylene
Cover material:	Polypropylene

Certificates

Test mark:	VDE (DIN EN 60670-1/-22 (VDE 0606-1/-22))
------------	---

Cable gland

$$2x \leq \varnothing 20 \text{ mm}$$

